


affinity™ series

HORIZONTAL DISCHARGE CONDENSING UNIT



YORK®

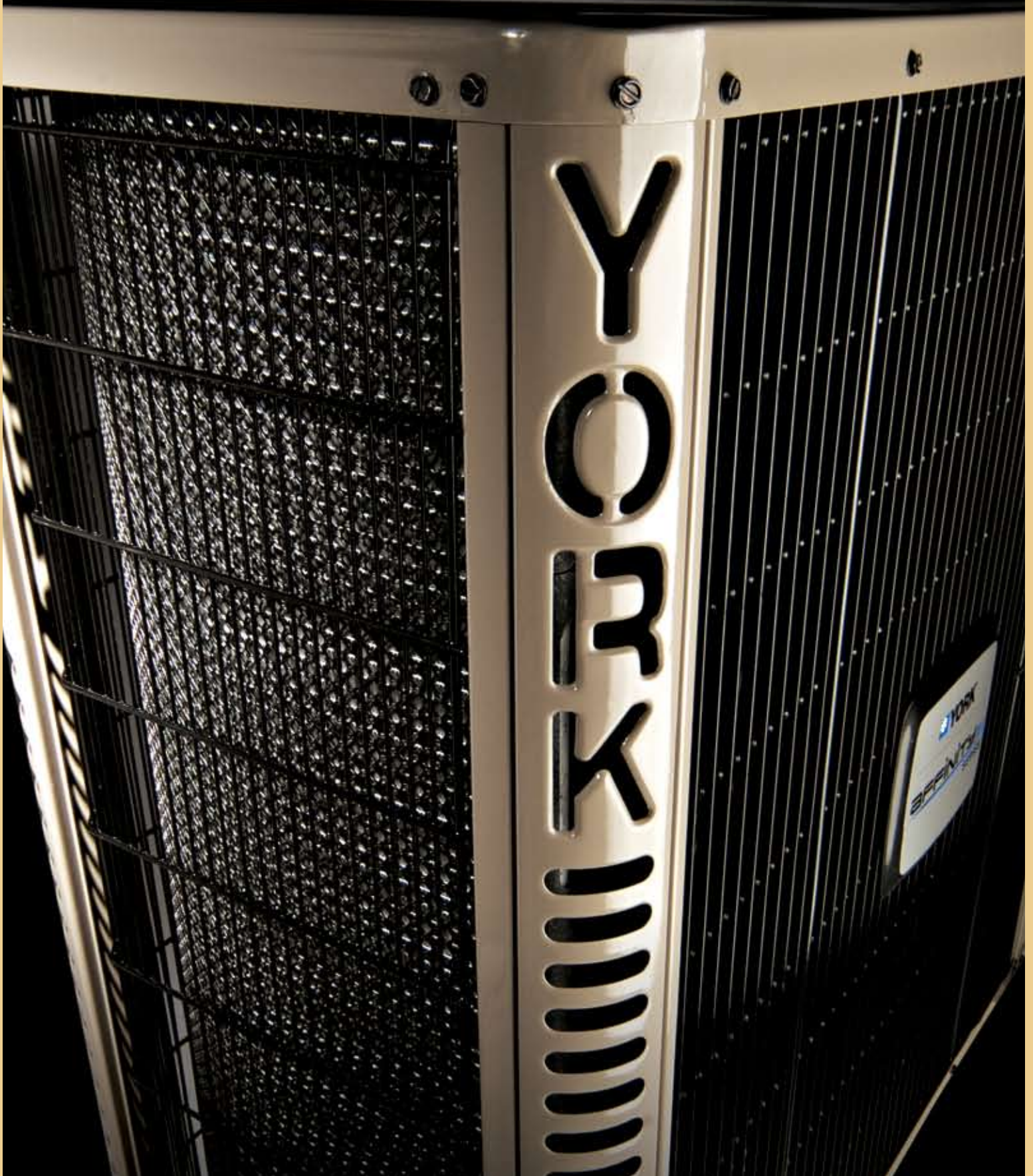

Affinity Series design and minimal-lot-line homes: a perfect fit.

With York's new Horizontal Discharge Affinity Series Condensing Unit, it really is possible to find innovative, energy-saving technology in a unit perfect for small yards and zero-lot-line homes. Nothing's been left out. Nothing's been compromised. This is the same Affinity Series design that homeowners have made so popular, all in a sleek model that will widen your list of potential sales.

Affinity Series Horizontal Discharge Condensing Unit

Big selling points.

- Sleek, premium style
- 1.5- to 5-ton capacity
- Great for tight space installations; only 6" clearance required on either air discharge or inlet
- Stackable
- Scroll compressor
- Blow-through design
- Unique fan design and isolated compressor compartment = super-quiet operation
- 10-year compressor warranty; 5-year parts warranty
- 3-phase models available in 2.5-, 3-, 4- and 5-ton sizes
- Industry-leading sound quality



*Microchannel coil technology utilizes all-aluminum materials providing greater corrosion resistance and uses up to 50% less refrigerant compared to conventional coils.

Big efficiency.

- Up to 15.5 SEER/13.5 EER
- Swept wing fan blade delivers greater efficiency compared to traditional blade design

Big durability.

- Corrosion-resistant coils hold up even in harsh seaside locales
- Air conditioning models feature [MC]2[®]* coil technology, making them long-lasting, light and easy to service—unlike units built with conventional coils
- Weather-resistant, automotive-grade powder coating
- Factory-supplied filter drier
- Accumulator and crankcase heater in all models
- Accommodates up to 200' line set
- High- and low-pressure switch

Affinity Series Horizontal Discharge Condensing Unit Models

AFFINITY SERIES HORIZONTAL DISCHARGE CONDENSING UNITS				DIMENSIONS			LIMITED WARRANTY	
Model	Tonnage	Nominal Efficiency	Refrigerant	Height	Width	Depth	Parts	Compressor
YCHD18S41S1	1.5 Tons	13 SEER	R410A	25 1/8"	37"	14 3/4"	5-Year	10-Year
YCHD24S41S1	2.0 Tons	13 SEER	R410A	25 1/8"	37"	14 3/4"	5-Year	10-Year
YCHD30S41S1*	2.5 Tons	13 SEER	R410A	37 1/8"	44 3/4"	17 1/4"	5-Year	10-Year
YCHD36S41S1*	3.0 Tons	13 SEER	R410A	37 1/8"	44 3/4"	17 1/4"	5-Year	10-Year
YCHD48S41S1*	4.0 Tons	13 SEER	R410A	43 1/8"	44 3/4"	17 1/4"	5-Year	10-Year
YCHD60S41S1*	5.0 Tons	13 SEER	R410A	43 1/8"	44 3/4"	17 1/4"	5-Year	10-Year

*Available in 208/230-3 and 460-3 voltages.



Unitary Products Group, Inc. 5005 York Drive, Norman, OK 73069 www.yorkupg.com
 Subject to change without notice. Copyright © by York International Corporation 2008.
 412496-YSS-A-0608 Supersedes: Nothing. All rights reserved.

